

vega D

The vega D enclosure is adapted for installations in houses and commercial premises up to 160 A. It can be delivered in a ready-to-mount configuration or to be completed. All the enclosures of this range have 24 modules rows.

	Page
vega D flush and surface enclosures	3
vega D equipped enclosures - accessories	5
vega D weatherproof IP 54	9

The flush mounting vega D enclosures can be installed in brick or partition walls (with a specific kit available as an option) and is made of 3 distinctive parts:

- a metallic flush mounting box
- a removable chassis
- a metallic finishing frame



FU22DN

Flush enclosures without door

Description	Pack qty.	Art No.
Encl., NewVegaD, 537x550x150mm, 48 mod.	1	FU22DN
Encl., NewVegaD, 687x550x150mm, 72 mod.	1	FU32DN
Encl., NewVegaD, 837x550x150mm, 96 mod.	1	FU42DN
Encl., NewVegaD, 987x550x150mm, 120 mod.	1	FU52DN
Encl., NewVegaD, 1137x550x150mm, 144 mod.	1	FU62DN
Encl., NewVegaD, 1287x550x150mm, 168 mod.	1	FU72DN



FU22AN

Flush enclosures, partially equipped, without door, high depth

Description	Pack qty.	Art No.
Encl., NewVegaD, 537x550x182mm, 48 mod.	1	FU22AN
Encl., NewVegaD, 687x550x182mm, 72 mod.	1	FU32AN
Encl., NewVegaD, 837x550x182mm, 96 mod.	1	FU42AN
Encl., NewVegaD, 987x550x182mm, 120 mod.	1	FU52AN
Encl., NewVegaD, 1137x550x182mm, 144 mod.	1	FU62AN
Encl., NewVegaD, 1287x550x182mm, 168 mod.	1	FU72AN



FU22GN

Flush enclosures to be completed

Description	Pack qty.	Art No.
Encl., NewVegaD, 537x550x182mm, 48 mod.	1	FU22GN
Encl., NewVegaD, 687x550x182mm, 72 mod.	1	FU32GN
Encl., NewVegaD, 837x550x182mm, 96 mod.	1	FU42GN
Encl., NewVegaD, 987x550x182mm, 120 mod.	1	FU52GN
Encl., NewVegaD, 1137x550x182mm, 144 mod.	1	FU62GN
Encl., NewVegaD, 1287x550x182mm, 168 mod.	1	FU72GN



FD22DN

Surface enclosures without door

Description	Pack qty.	Art No.
Encl., NewVegaD, 450x500mm, 48 mod.	1	FD22DN
Encl., NewVegaD, 600x550x193mm, 72 mod.	1	FD32DN
Encl., NewVegaD, 750x550x193mm, 96 mod.	1	FD42DN
Encl., NewVegaD, 900x550x193mm, 120 mod.	1	FD52DN
Encl., NewVegaD, 1050x550x193mm, 144 mod.	1	FD62DN
Encl., NewVegaD, 1200x550x193, 168 mod.	1	FD72DN



FD22AN

Surface enclosures, to be completed, without door

Description	Pack qty.	Art No.
Encl., NewVegaD, 450x550x193mm, 48 mod.	1	FD22AN
Encl., NewVegaD, 600x550x193mm, 72 mod.	1	FD32AN
Encl., NewVegaD, 750x550x193mm, 96 mod.	1	FD42AN
Encl., NewVegaD, 900x550x193mm, 120 mod.	1	FD52AN
Encl., NewVegaD, 1050x550x193mm, 144 mod.	1	FD62AN
Encl., NewVegaD, 1200x550x193, 168 mod.	1	FD72AN

Surface enclosures to be completed

Description	Pack qty.	Art No.
Encl., NewVegaD, 450x550x193mm, 48 mod.	1	FD22GN
Encl., NewVegaD, 600x550x193mm, 72 mod.	1	FD32GN
Encl., NewVegaD, 750x550x193mm, 96 mod.	1	FD42GN
Encl., NewVegaD, 900x550x193mm, 120 mod.	1	FD52GN
Encl., NewVegaD, 1050x550x193mm, 144 mod.	1	FD62GN
Encl., NewVegaD, 1200x550x193, 168 mod.	1	FD72GN



FD22GN



FD22PN

Plain doors

Description	Pack qty.	Art No.
Plain door, NewVegaD, H400 W500 mm	1	FD22PN
Plain door, NewVegaD, H550 W500 mm	1	FD32PN
Plain door, NewVegaD, H700 W500 mm	1	FD42PN
Plain door, NewVegaD, H850 W500mm	1	FD52PN
Plain door, NewVegaD, H1000 W500 mm	1	FD62PN
Plain door, NewVegaD, H1150 W500 mm	1	FD72PN



FD22TN

Transparent doors

 
Description	Pack qty.	Art No.
Glazed door, NewVegaD, H400 W500 mm	1	FD22TN
Glazed door, NewVegaD, H550 W500 mm	1	FD32TN
Glazed door, NewVegaD, H700 W500 mm	1	FD42TN
Glazed door, NewVegaD, H850 W500 mm	1	FD52TN
Glazed door, NewVegaD, H1000 W500 mm	1	FD62TN
Glazed door, NewVegaD H1100 W500 mm	1	FD72TN



FD01A1

Equipment units

Description	Pack qty.	Art No.
Kit, NewVegaD, 150x500mm, 1x24 mod.	1	FD01A1
Kit, NewVegaD, 150x500mm, depth-adjust.	1	FD01A2
Kit, NewVegaD, 150x500mm, for MCCB 160A	1	FD01K1
Kit, NewVegaD, 300x500mm, for MCCB 160A	1	FD02K1
Kit, NewVegaD, 300x500mm, 2x24 mod.	1	FD02A1
Kit, NewVegaD, 300x500mm, depth-adjust.	1	FD02A2
Kit, NewVegaD, 300x500mm, 1x24 mod.+depth.	1	FD02A3
Kit, NewVegaD, 300x500mm, depth-adjust.	1	FD02C2



FD00T1

Trunking

Description	Pack qty.	Art No.
Slotted trunking 80x30 grey NewVegaD	1	FD00T1
Slot. trunking, NewVegaD, 80x30mm, lightgr.	1	FD00T2




FD00C1

Cover plates

Description	Pack qty.	Art No.
Cover, NewVegaD, 300x500mm, slotted	1	FD00C1
Cover, NewVegaD, 300x500mm, plain	1	FD00C2
Cover, NewVegaD, 300x500mm, plain+slotted	1	FD00C3
Cover, NewVegaD, 150x500mm slotted	1	FD00C4
Cover, NewVegaD, 150x500mm, plain	1	FD00C5

Mounting plates

Description	Pack qty.	Art No.
Perforated plate, NewVegaD, 225x440mm	1	FD00M1
Mounting plate, NewVegaD, 300x440mm	1	FD00M2
Perforated plate, NewVegaD, 150x440mm	1	FD00M3
Mounting plate, NewVegaD, 150x440mm	1	FD00M4

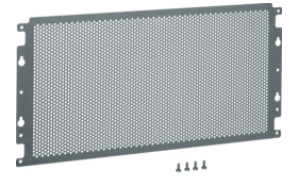

FD00M1

Accessories

Description	Pack qty.	Art No.
Kit with basis holder, NewVegaD	1	FD00H1
Kit with DIN rail holder, NewVegaD	1	FD00H2
Label strips Kit, NewVegaD, 10pcs.	1	FD00A1
Partition plate, NewVegaD, horiz.	1	FD00A3
Kit NewVegaD, w. cable brackets surface	1	FD00B1
Kit NewVegaD, w. cable brackets flush	1	FD00B2
PEN Quick-connect holder, NewVegaD	1	FD00Q1
Transmission clamp, universN, 20 pcs.	1	UZ25V1
Transmission clamp, universN, 20 pcs.	1	UZ25V2
Adaptor, universN, double, 20pcs	1	UZ01V1



FD00H1

Cable entry plates

Description	Pack qty.	Art No.
Cable entry plate, NewVegaD, rectangular	1	FD00P1
Cable entry plate, NewVegaD, w. 2x flange	1	FD00P2
Cable entry plate, NewVegaD, w. knock-out	1	FD00P3
Kit, NewVegaD, with side plates	1	FD00P4
Rear flange IP41, NewVegaD, Univers FW	1	VZ741



FD00P1

45x45mm adapter for systo


Description	Pack qty.	Art No.
Adapter NewVegaD, for Systo accessories	1	FD00E1



FD00E1

Vertical and horizontal association kit

Description	Pack qty.	Art No.
Kit encl.-encl. Association, NewVegaD	1	FD00F1

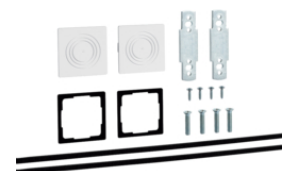

FD00F1

**Wall fixation brackets**

Description	Pack qty.	Art No.
Kit, NewVegaD, external wall-mounting	1	FD00F2

FD00F2

**Cable strain relief bar**

Description	Pack qty.	Art No.
Cable strain relief bar, NewVegaD, 24 Mod.	1	FD00F3

FD00F3

**DIN rails**

Description	Pack qty.	Art No.
DIN rails, universN, 15mm, 2pcs, 24PLE	1	UZ02B9

UZ02B9

**A4 pocket plan**

Description	Pack qty.	Art No.
Document holder, T, DIN A4	10	FZ794

FZ794

**Blanking clips**

Description	Pack qty.	Art No.
Cover strips, universal, for 1/2 module	50	P031F
Cover strips, universal, for 1 module	50	P032F

P031F

Blanking strips

Description	Pack qty.	Art No.
Cover strip, universal, 24M, RAL 9010	10	JP002



JP002

Locks

Description	Pack qty.	Art No.
Kit, NewVegaD, standard lock	1	FD00S0
Kit, NewVegaD, key lock 1242E	1	FD00S1
Kit, key lock triangle, 7mm, f. NewVegaD	1	FD00S2
Kit, key lock square, 7mm, f. NewVegaD	1	FD00S3
Kit, key lock NewVegaD, Nr. 405	1	FD00S4
Kit, NewVegaD, key lock two-way, 3mm	1	FD00S5



FD00S0

Single pole distribution blocks

Description	Pack qty.	Art No.
Distribution block, 125A, 1 pole	4	KJ02D
Distribution block, 160A, 1 pole	4	KJ02C



KJ02D

Modular distribution monobloc

Description	Pack qty.	Art No.
Distribution block 125A, closed, 4pole	1	KJ02E



KJ02E

Stepped distribution blocks, brass busbar terminals

Description	Pack qty.	Art No.
Brass busbar terminal 100A, 4pole	1	KJ100A
Brass busbar terminal 125A, 4pole	1	KJ125B
Brass busbar terminal 160A, 4pole	1	KJ160A



KJ100A

The weatherproof IP54 vega D enclosure is equipped with:

- removable cable entries on top and bottom

- removable chassis with uprights and units for modular devices



FV22A

IP 54 to be completed

Description	Pack qty.	Art No.
Encl., VegaD IP55, 500x550x275mm, empty	1	FV22A
Encl., VegaD IP55, 650x550x275mm, 24mod.	1	FV32A
Encl., VegaD IP55, 800x550x275mm, 48mod.	1	FV42A
Encl., VegaD IP55, 950x550x275mm, 72mod.	1	FV52A
Encl., VegaD IP55, 1100x550x275mm, 96mod	1	FV62A
Encl., VegaD IP55, 1250x550x275mm, 120mod	1	FV72A



UK22A2

Equipment units

Description	Pack qty.	Art No.
Kit, universN, 300x500mm, MCCB x160A	1	UK22A2
Kit, universN, 300x500mm, MCCB x250A	1	UK22B3
Kit, universN, 300x500mm, 2x24 M	1	UD22B3
Kit, universN, 300x500mm, DIN rail terminal	1	UD22A5



FZ507

Locks

Description	Pack qty.	Art No.
Lock, univers, T-handle w. cyl-Nr.E1242	1	FZ507
Lock, univers, T-handle w. cyl-Nr.E405	1	FZ526
Lock, univers, T-handle w. cyl-Nr.E455	1	FZ527
Lock, univers, square, 7mm	1	FZ503
Lock, univers, triangular 7mm	1	FZ502
Lock, univers, double-bit 3mm	1	FZ501



UZ25V1

Wire guides

Description	Pack qty.	Art No.
Transmission clamp, universN, 20 pcs.	1	UZ25V1
Transmission clamp, universN, 20 pcs.	1	UZ25V2



UT50C

Covers for wire guide

Description	Pack qty.	Art No.
Cover trunking, universN, 78x31mm, 2m	20	UT50C

Horizontal wire ducts

Description	Pack qty.	Art No.
Cable trunking, universN, 78x31mm, 2sect	1	UZ52A1



UZ52A1

Support frame for wire ducts

Description	Pack qty.	Art No.
Holder for cable trunking, universN, 2pcs	1	UZ50A1



UZ50A1

Blanking clips

Description	Pack qty.	Art No.
Cover strips, universal, for 1/2 module	50	P031F
Cover strips, universal, for 1 module	50	P032F



P031F

Blanking strips

Description	Pack qty.	Art No.
Cover strip, universal, 24M, RAL 9010	10	JP002



JP002

A4 pocket plans

Description	Pack qty.	Art No.
Document holder, T, DIN A4	10	FZ794



FZ794



KJ02D

Distribution blocks

Description	Pack qty.	Art No.
Distribution block, 125A, 1pole	4	KJ02D
Distribution block, 160A, 1pole	4	KJ02C
Distribution block, 250A, 1pole	4	KJ02A
Distribution block 400A, closed, 1pole	4	KJ02B



KJ02E

Modular distribution monobloc

Description	Pack qty.	Art No.
Distribution block 125A, closed, 4pole	1	KJ02E



KJ100A

Stepped distribution blocks, brass busbar terminals

Description	Pack qty.	Art No.
Brass busbar terminal 100A, 4pole	1	KJ100A
Brass busbar terminal 125A, 4pole	1	KJ125B
Brass busbar terminal 160A, 4pole	1	KJ160A