




MMN200



## 2 P.P. magnétique 25 kA

Description	Cond.	Référence
Disj.mag.2P 25kA 0.63A 2m	1	<b>MMN200</b>
Disj.mag.2P 25kA 1.25A 2m	1	<b>MMN201</b>
Disj.mag.2P 25kA 1.60A 2m	1	<b>MMN202</b>
Disj.mag.2P 25kA 2.5A 2m	1	<b>MMN203</b>
Disj.mag.2P 25kA 4A 2m	1	<b>MMN204</b>
Disj.mag.2P 25kA 6.3A 2m	1	<b>MMN206</b>
Disj.mag.2P 25kA 10A 2m	1	<b>MMN210</b>
Disj.mag.2P 25kA 12A 2m	1	<b>MMN213</b>
Disj.mag.2P 20kA 16A 2m	1	<b>MMN216</b>
Disj.mag.2P 20kA 20A 2m	1	<b>MMN220</b>
Disj.mag.2P 20kA 25A 2m	1	<b>MMN225</b>

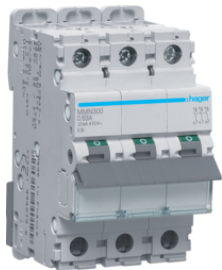

MMN300



## 3 P.P. magnétique 25 kA

Description	Cond.	Référence
Disj.mag.3P 25kA 0.63A 3m	1	<b>MMN300</b>
Disj.mag.3P 25kA 1.25A 3m	1	<b>MMN301</b>
Disj.mag.3P 25kA 1.60A 3m	1	<b>MMN302</b>
Disj.mag.3P 25kA 2.5A 3m	1	<b>MMN303</b>
Disj.mag.3P 25kA 4A 3m	1	<b>MMN304</b>
Disj.mag.3P 25kA 6.3A 3m	1	<b>MMN306</b>
Disj.mag.3P 25kA 10A 3m	1	<b>MMN310</b>
Disj.mag.3P 25kA 12A 3m	1	<b>MMN313</b>
Disj.mag.3P 20kA 16A 3m	1	<b>MMN316</b>
Disj.mag.3P 20kA 20A 3m	1	<b>MMN320</b>
Disj.mag.3P 20kA 25A 3m	1	<b>MMN325</b>